



PRESSURE BOOSTERS

# THE CME BOOSTER

be  
think  
innovate

GRUNDFOS 

# The CME Booster

The Grundfos CME Booster provides constant water pressure for a variety of domestic applications, regardless of changing demands.


The CME also enables users to personalise water pressure, increasing or decreasing pressure at the touch of a button.



# Applications

The CMB is designed to boost water supply in domestic applications.

It can connect to city mains either directly or via a break tank.

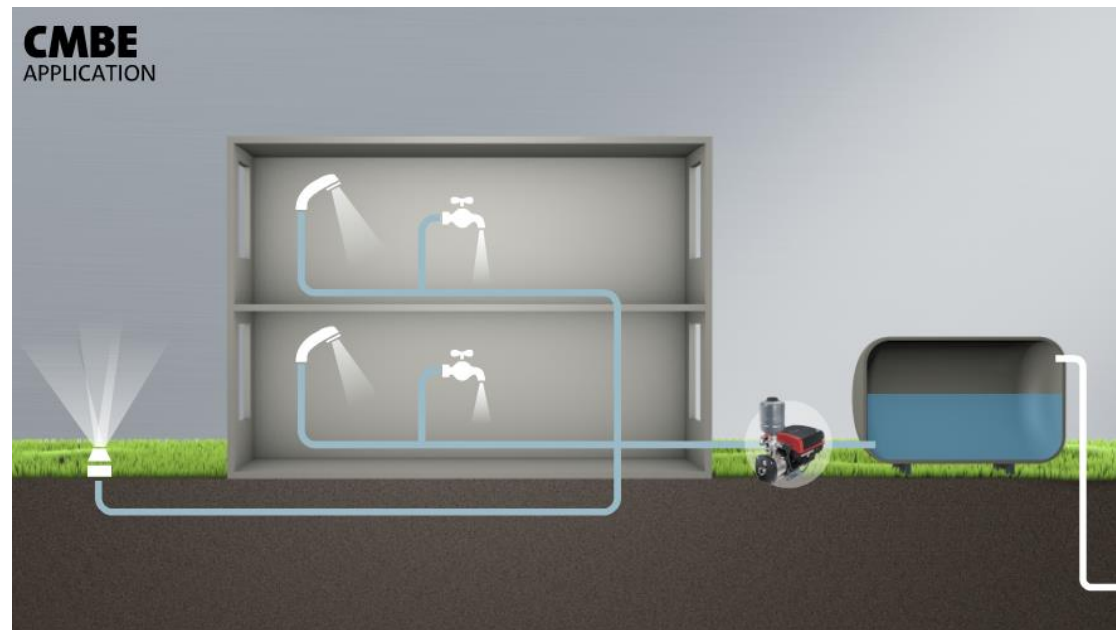


# Main benefits





- Cruise Control – always constant pressure
- All-in-one system – plug & pump
- Low noise operation  $\leq 55$  dB(A)
- Dry run & overload protection
- 2-year warranty

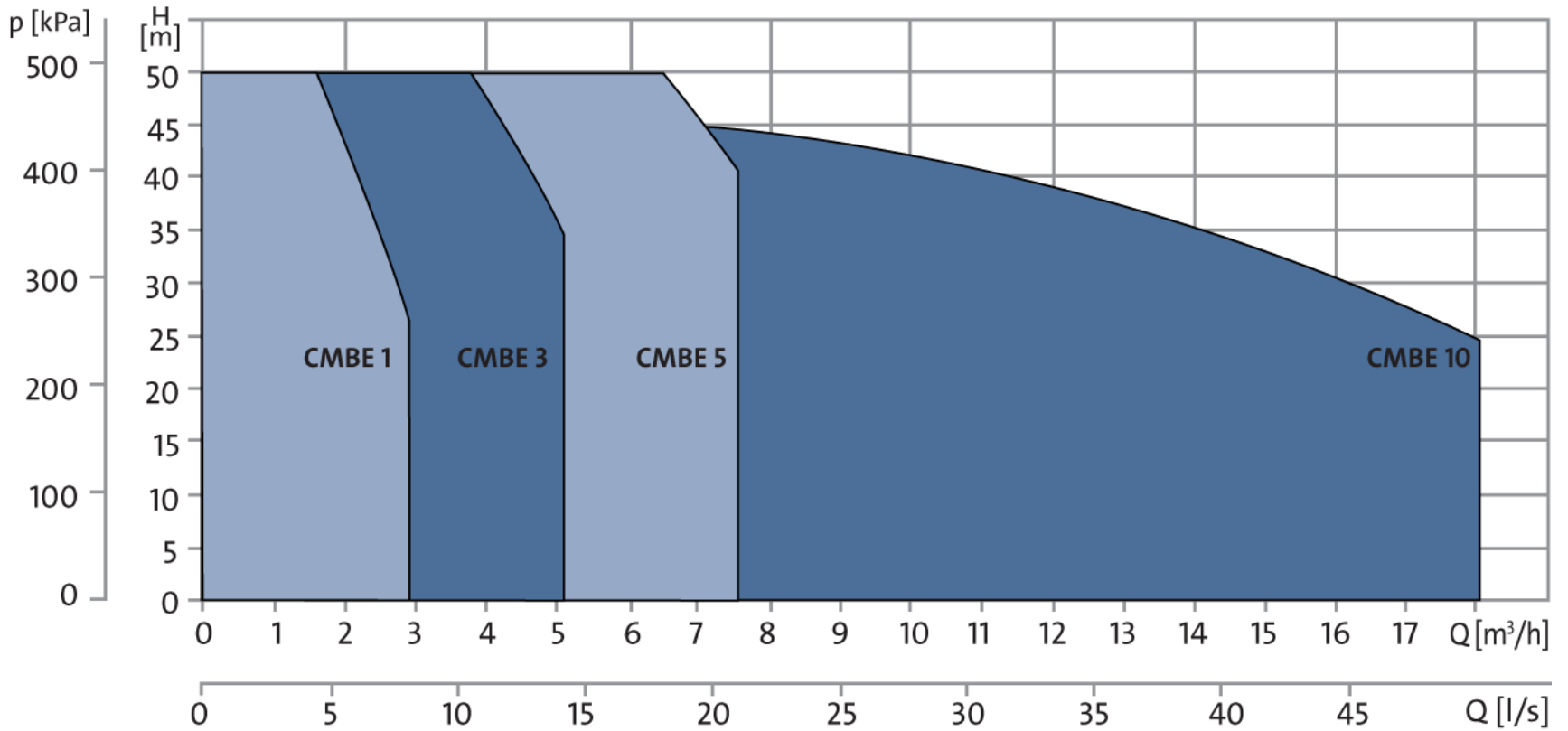

# Performance



# Selection

TAPS		FLOORS			
		1 - 5	6 - 10	11 - 20	21 - 50
	4	<b>CMBE 3-4</b>	<b>CMBE 3-4</b>	<b>CMBE 3-4</b>	
	3	<b>CMBE 3-3</b>	<b>CMBE 3-3</b>	<b>CMBE 3-4</b>	<b>CMBE 5-3</b>
	2	<b>CMBE 1-4</b>	<b>CMBE 3-3</b>	<b>CMBE 3-3</b>	<b>CMBE 3-4</b>
	1	<b>CMBE 1-4</b>	<b>CMBE 1-4</b>	<b>CMBE 3-3</b>	<b>CMBE 3-4</b>

# Operating conditions & technical data

## Operating conditions

- System pressure: Max. 7.5 bar
- Liquid temperature: 0° C to +60° C
- Ambient temperature: Max. +55° C
- Relative air humidity: Max. 95%

## Technical data

- Mains voltage: 1x 220-240V, 50/60Hz
- Enclosure class: IP55
- Sound pressure level: <= 55 dB(A)
- Start/stop frequency: Max. 100 per hour
- Approvals: Drinking water approved



# GRUNDFOS **ECADEMY**

[www.grundfos.com](http://www.grundfos.com)