

Compact Boosting Pump

GRUNDFOS CMBE

The CMBE Booster is designed for residential and commercial water supply, pressure boosting, irrigation and dewatering applications. The CMBE series is available in both 1x110-120V and 1x200-240V variants and uses energy efficient, permanent magnet motor technology, which provides unmatched reliability, quiet operation, and energy savings.

Thanks to the integrated speed controller, the CMBE keeps a constant pressure in the pipe system. A pressure sensor monitoring discharge pressure will signal to the speed controller to change the motor speed to adapt the performance to the new situation.



KEY FEATURES AND BENEFITS

- All-in-one solution including pump, motor, tank, pressure and flow sensor, controller and check valve
- Constant pressure and commercial grade quality in one compact system
- Reliable and easy to install
- Highly efficient ECM motor reduces operating costs
- Variable Frequency Drive (VFD) with built in PI controller
- Grundfos manufactures all CMBE component
- Optimized and simple to use controller
- Communication capable with CIM cards
- Simple selection guide to size correct pump
- Low noise (55dB or less in typical use)
- Drinking water NSF 61/UL 372 approved

APPLICATIONS

- Residential and commercial water supply
- Pressure boosting
- Irrigation
- Dewatering


TECHNICAL DATA

CMBE	
SYSTEM PRESSURE:	max. 145 psi
SUCTION LIFT:	max. 23 ft including suction-pipe pressure loss at a liquid temperature of 68°F
LIQUID TEMPERATURE:	32°F to +140°F
AMBIENT TEMPERATURE:	max. 113 °F for 115V max. 122 °F for 220V min. -4 °F
SOUND PRESSURE LEVEL:	max. 55 dB(A)
SUPPLY VOLTAGE:	1x115 V, 1x200-240 V, 60 Hz

PRODUCT OFFERING

98810910	CMBE 1-44 1x115V 60 Hz
98548109	CMBE1-44 1x200-240V 50/60 Hz
98810921	CMBE 1-75 1x115V 60 Hz
98548110	CMBE 1-75 50/60 Hz
98548111	CMBE 1-99 50/60 Hz
98810922	CMBE 3-30 1x115V 60 Hz
98548112	CMBE 3-30 50/60 Hz
98810924	CMBE 3-51 1x115V 60 Hz
98548113	CMBE 3-62 1x200-240V 50/60 Hz
98548114	CMBE 3-93 1x200-240V 50/60 Hz
98548115	CMBE 5-31 1x200-240V 50/60 Hz
98548116	CMBE 5-62 1x200-240V 50/60 Hz
98548118	CMBE 10-54 1x200-240V 50/60 Hz

PERFORMANCE DATA

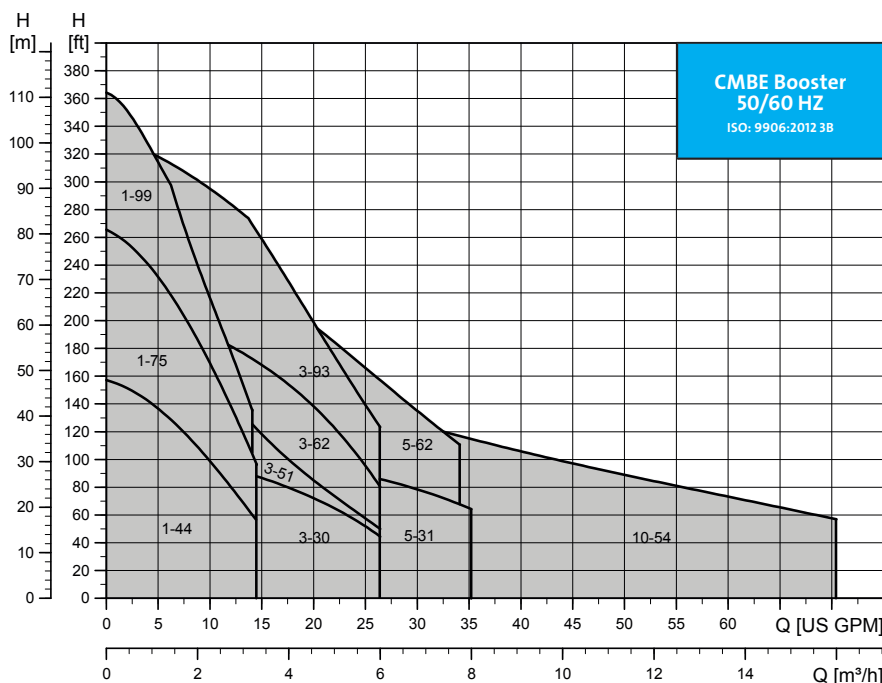

Trademarks displayed in this material, including but not limited to Grundfos, the Grundfos logo and "be think innovate" are registered trademarks owned by The Grundfos Group. All rights reserved. © 2019 Grundfos Holding A/S, all rights reserved. L-CMB-5-L02-07-19